

# Trunking Systems



# 10

## Page

---

DNG Slotted Trunking	328
SL Floor Trunking	329
EK 'Chameleon' Corner Trunking	330
Technical Information	330

---

\*Note that cable management products are indent items.  
Please check availability with your local Hager sales office at the time of order.

### DNG Slotted Trunking supplied as

- Based (pre-drilled) and lid

### Temperature range

- -5°C to +65°C

### Material

- Rigid PVC

### Standard length

- 2000mm

### Colour

- RAL7030 grey (GR)

HNG Halogen-free trunking available upon request.

### Technical information:

[Page 330](#)

\*Please check availability with your local Hager sales office at time of order



DNG10005007030B

### DNG Slotted Trunking

Description	Pack qty (lengths)	Slot config.	Cat ref.
20h x 20w slotted trunking	32	B	<b>DNG2002007030B*</b>
25h x 25w slotted trunking	24	A	<b>DNG2502507030B*</b>
25h x 37w slotted trunking	32	A	<b>DNG2503707030B*</b>
37h x 20w slotted trunking	16	B	<b>DNG3702007030B*</b>
37h x 37w slotted trunking	16	A	<b>DNG3703707030B*</b>
50h x 25w slotted trunking	19	A	<b>DNG5002507030B*</b>
50h x 37w slotted trunking	20	A	<b>DNG5003707030B*</b>
50h x 50w slotted trunking	24	A	<b>DNG5005007030B*</b>
50h x 75w slotted trunking	10	A	<b>DNG5007507030B*</b>
50h x 100w slotted trunking	12	A	<b>DNG5010007030B*</b>
75h x 25w slotted trunking	16	A	<b>DNG7502507030B*</b>
75h x 37w slotted trunking	20	A	<b>DNG7503707030B*</b>
75h x 50w slotted trunking	10	A	<b>DNG7505007030B*</b>
75h x 75w slotted trunking	18	A	<b>DNG7507507030B*</b>
75h x 100w slotted trunking	18	A	<b>DNG7510007030B*</b>
100h x 50w slotted trunking	12	A	<b>DNG10005007030B*</b>
100h x 75w slotted trunking	18	A	<b>DNG10007507030B*</b>
100h x 100w slotted trunking	16	A	<b>DNG10010007030B*</b>



LK750503

### Cable Retainers

Description	Pack qty (lengths)	Cat ref.
Cable retainer for DNG75037	50	<b>DN750373*</b>
Cable retainer for DNG75050	50	<b>LK750503*</b>
Cable retainer for DNG75075	50	<b>LK750753*</b>
Cable retainer for DNG75100	50	<b>LK751003*</b>
Cable retainer for DNG100050	50	<b>DN1000503*</b>
Cable retainer for DNG100075	50	<b>DN1000753*</b>
Cable retainer for DNG100100	50	<b>DN1001003*</b>



DN3702027030

### Lids only

Description	Pack qty (lengths)	Cat ref.
To suit 20mm width	20	<b>DN3702027030*</b>
To suit 37mm width	20	<b>DN3703727030*</b>
To suit 50mm width	20	<b>DN5005027030*</b>
To suit 75mm width	20	<b>DN5007527030*</b>
To suit 100mm width	20	<b>DN5010027030*</b>

**SL Floor Trunking supplied as**

- SL11040: cable cover
- SL18075: base (pre-drilled) and cover

**Temperature**

- -5°C to +65°C

**Material:**

- Rigid PVC

**Standard length**

- 2000mm

**Colour**

- RAL7030 grey
- RAL9001 cream white

**EK Chameleon Trunking supplied as**

- base (pre-drilled) and cover

**Temperature range**

- -5°C to +65°C

**Material**

- Rigid PVC

**Standard length**

- 2500mm

**Colour**

- RAL9010 pure white

Technical information [Page 331](#)

\*Please check availability with your local Hager sales office at time of order

**SL Floor Trunking**

Description	Pack qty (lengths)	Colour	Cat ref.
11 x 40 floor trunking	35	grey	<b>SL1104007030*</b>
18 x 75 4 channel floor trunking	16	grey	<b>SL1807507030*</b>



SL1104007030



SL1807507030

**EK 'Chameleon' Corner Trunking**

Description	Pack qty (lengths)	Cat ref.
40h x 40w 2 channel trunking	20	<b>EK4004009010*</b>




EK4004009010




EK4004009010


### DNG Slotted Trunking dimensions

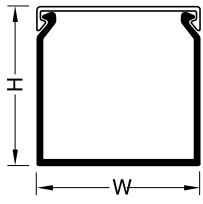


Cross section

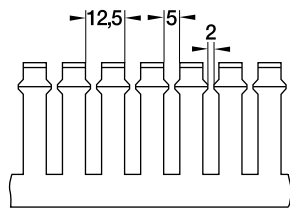


Slot configuration A

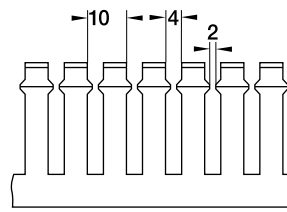

Slot configuration B

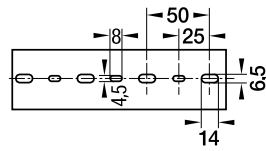


Base punching configuration for trunking widths 20, 25, 37 and 50mm to DIN 43659

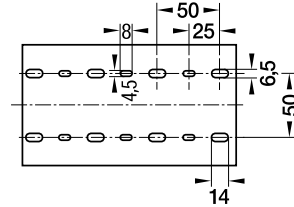


Base punching configuration for trunking widths 75, and 100mm to DIN 43659

SL Floor Trunking dimensions

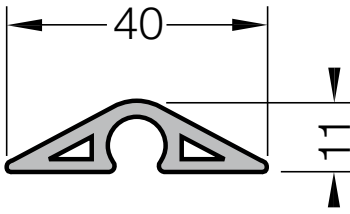


11 x 40 floor trunking  
cross section

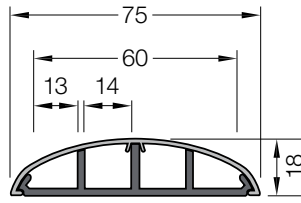

4 channel floor trunking  
cross section

EK chameleon trunking dimensions

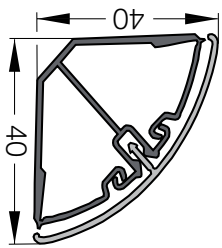

Cross section