


Trunking Systems

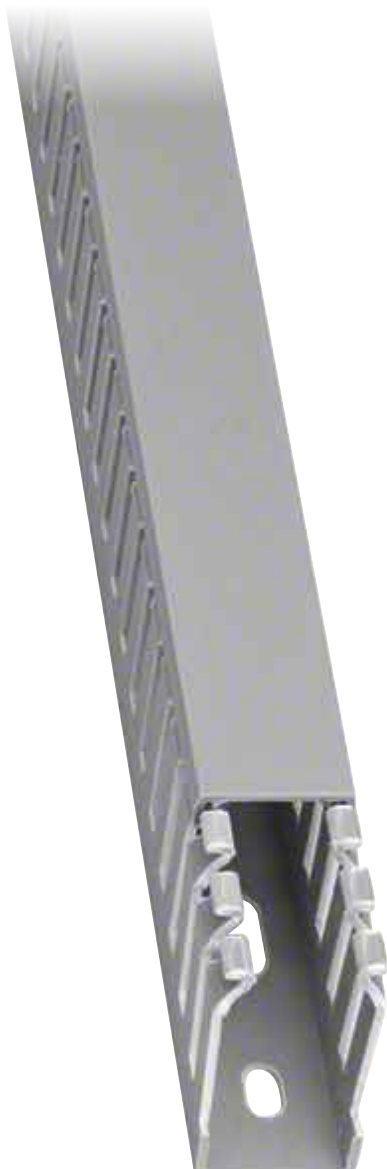

10

Page

DNG Slotted Trunking	500
SL Floor Trunking	501
EK 'Chameleon' Corner Trunking	501
Technical Information	502

*Note that cable management products are indent items.
Please check availability with your local Hager sales office at the time of order.

DNG Slotted Trunking supplied as

- Based (pre-drilled) and lid

Temperature range

- -5°C to +65°C

Material

- Rigid PVC

Standard length

- 2000mm

Colour

- RAL7030 grey (GR)

HNG Halogen-free trunking available upon request.

Technical information:

[Page 502](#)

*Please check availability with your local Hager sales office at time of order



DNG10005007030B

DNG Slotted Trunking

Description	Pack qty (lengths)	Slot config.	Cat ref.
20h x 20w slotted trunking	32	B	DNG2002007030B*
25h x 25w slotted trunking	24	A	DNG2502507030B*
25h x 37w slotted trunking	32	A	DNG2503707030B*
37h x 20w slotted trunking	16	B	DNG3702007030B*
37h x 37w slotted trunking	16	A	DNG3703707030B*
50h x 25w slotted trunking	19	A	DNG5002507030B*
50h x 37w slotted trunking	20	A	DNG5003707030B*
50h x 50w slotted trunking	24	A	DNG5005007030B*
50h x 75w slotted trunking	10	A	DNG5007507030B*
50h x 100w slotted trunking	12	A	DNG5010007030B*
75h x 25w slotted trunking	16	A	DNG7502507030B*
75h x 37w slotted trunking	20	A	DNG7503707030B*
75h x 50w slotted trunking	10	A	DNG7505007030B*
75h x 75w slotted trunking	18	A	DNG7507507030B*
75h x 100w slotted trunking	18	A	DNG7510007030B*
100h x 50w slotted trunking	12	A	DNG10005007030B*
100h x 75w slotted trunking	18	A	DNG10007507030B*
100h x 100w slotted trunking	16	A	DNG10010007030B*



LK750503

Cable Retainers

Description	Pack qty (lengths)	Cat ref.
Cable retainer for DNG75037	50	DN750373*
Cable retainer for DNG75050	50	LK750503*
Cable retainer for DNG75075	50	LK750753*
Cable retainer for DNG75100	50	LK751003*
Cable retainer for DNG100050	50	DN1000503*
Cable retainer for DNG100075	50	DN1000753*
Cable retainer for DNG100100	50	DN1001003*



DN3702027030

Lids only

Description	Pack qty (lengths)	Cat ref.
To suit 20mm width	20	DN3702027030*
To suit 37mm width	20	DN3703727030*
To suit 50mm width	20	DN5005027030*
To suit 75mm width	20	DN5007527030*
To suit 100mm width	20	DN5010027030*

SL Floor Trunking supplied as

- SL11040: cable cover
- SL18075: base (pre-drilled) and cover

Temperature

- -5°C to +65°C

Material:

- Rigid PVC

Standard length

- 2000mm

Colour

- RAL7030 grey
- RAL9001 cream white

EK Chameleon Trunking supplied as

- base (pre-drilled) and cover

Temperature range

- -5°C to +65°C

Material

- Rigid PVC

Standard length

- 2500mm

Colour

- RAL9010 pure white

Technical information [Page 503](#)

*Please check availability with your local Hager sales office at time of order

SL Floor Trunking

Description	Pack qty (lengths)	Colour	Cat ref.
11 x 40 floor trunking	35	grey	SL1104007030*
18 x 75 4 channel floor trunking	16	grey	SL1807507030*



SL1104007030



SL1807507030

EK 'Chameleon' Corner Trunking

Description	Pack qty (lengths)	Cat ref.
40h x 40w 2 channel trunking	20	EK4004009010*




EK4004009010




EK4004009010


DNG Slotted Trunking dimensions

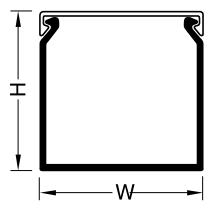


Cross section

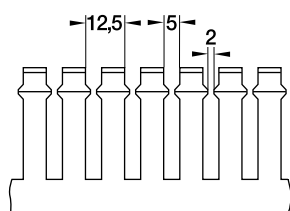


Slot configuration A

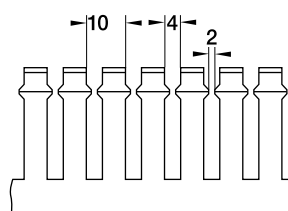

Slot configuration B

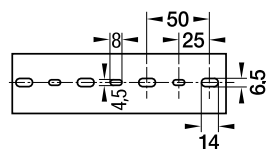


Base punching configuration for trunking widths 20, 25, 37 and 50mm to DIN 43659

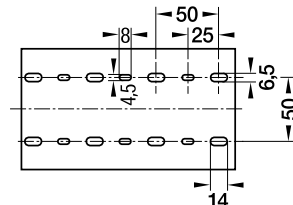


Base punching configuration for trunking widths 75, and 100mm to DIN 43659

SL Floor Trunking dimensions

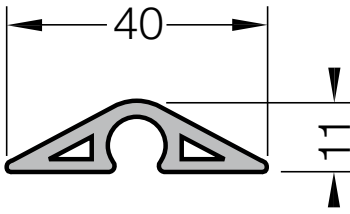


11 x 40 floor trunking
cross section

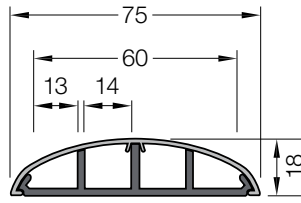

4 channel floor trunking
cross section

EK chameleon trunking dimensions

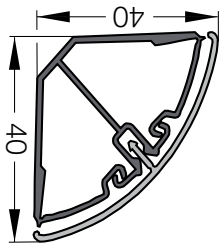

Cross section