

Residential trunking

Easy to install and offering great finishes, our range of residential trunking is suitable for renovation or extension of the installations in houses and small professional premises.

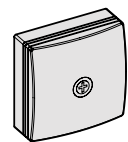


tehalit.atoha	8.2
tehalit.SL	8.8
Accessories for tehalit.atoha	8.12
Technical guide	8.13

Delivery information: Base and lid together (lid opening with screwdriver) and 2 cables retainers/m (except 12x20).
Standard length: 2m, except for sizes: 12x20, 12x30, 16x30 and 6x30 (2,10 m). Other length on demand, max. 6 m.
Material: Rigid PVC. **Protection category:** IP 40, IK 07.

Note: The colour code indicates compatibility between accessories and trunkings.

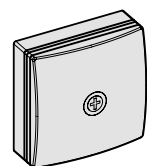
		Base and lid	Adjustable external corner	Adjustable internal corner	Flat corner	End cap
		Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
	pure white	ATA122009010	ATA122039010	ATA122049010	ATA122059010	ATA122069010
	brown	ATA122008014	ATA122038014	ATA122048014	ATA122058014	ATA122068014
	packaging	84 m	40 pieces	40 pieces	40 pieces	40 pieces
	pure white	ATA122019010	ATA122039010	ATA122049010	ATA122059010	ATA122069010
	brown	ATA122018014	ATA122038014	ATA122048014	ATA122058014	ATA122068014
	packaging	84 m	40 pieces	40 pieces	40 pieces	40 pieces
	pure white	ATA123009010	ATA123039010	ATA123049010	ATA123059010	ATA123069010
	brown	ATA123008014	ATA123038014	ATA123048014	ATA123058014	ATA123068014
	packaging	60 m	40 pieces	40 pieces	40 pieces	40 pieces
	pure white	ATA123019010	ATA123039010	ATA123049010	ATA123059010	ATA123069010
	brown	ATA123018014	ATA123038014	ATA123048014	ATA123058014	ATA123068014
	packaging	60 m	40 pieces	40 pieces	40 pieces	40 pieces
	pure white	ATA163009010	ATA163039010	ATA163049010	ATA163059010	ATA163069010
	brown	ATA163008014	ATA163038014	ATA163048014	ATA163058014	ATA163068014
	packaging	50 m	20 pieces	20 pieces	20 pieces	20 pieces
	pure white	ATA163019010	ATA163039010	ATA163049010	ATA163059010	ATA163069010
	brown	ATA163018014	ATA163038014	ATA163048014	ATA163058014	ATA163068014
	packaging	50 m	20 pieces	20 pieces	20 pieces	20 pieces
	pure white	ATA630009010				
	packaging	46 m				



ATA70759

Connection boxes 75 x 75 x 32 mm



Description	Pack qty.	Cat. ref.
pure white (9010)	10	ATA707599010
brown (8014)	10	ATA707598014

 
 
 
 
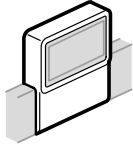
 
 
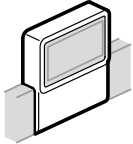


ATA71159

Connection boxes 115 x 115 x 52 mm

Description	Pack qty.	Cat. ref.
pure white (9010)	8	ATA711599010
brown (8014)	8	ATA711598014

 
Colours:  pure white (9010)
 brown (8014)

Joint cover	T, and deviation piece	Adaptator ATA / SL with EK corner trunking	Socket box 1-gang empty for Legrand outlet (1x45mm)	Socket box 2-gang empty for Legrand outlet (2x45mm)	Socket box 1-gang empty Alrea™ outlet (1x45mm)	Socket box 1-gang outlet for ateha	Socket box 2-gang outlet for ateha
							
Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
ATA122079010	ATA122089010	M55609010	ATA122199010	ATA122499010	ATA122399010	ATA12391	ATA12392
ATA122078014	ATA122088014		ATA122198014				
40 pieces	20 pieces	5 pieces	20 pieces	10 pieces	20 pieces	20 pieces	10 pieces
ATA122079010	ATA122089010	M55609010	ATA122199010	ATA122499010	ATA122399010	ATA12391	ATA12392
ATA122078014	ATA122088014		ATA122198014	ATA122498014			
40 pieces	20 pieces	5 pieces	20 pieces	10 pieces	20 pieces	20 pieces	10 pieces
ATA123079010	ATA123089010	M55609010	ATA123199010	ATA123499010	ATA123399010	ATA12391	ATA12392
ATA123078014	ATA123088014		ATA123198014	ATA123498014			
40 pieces	20 pieces	5 pieces	20 pieces	10 pieces	20 pieces	20 pieces	10 pieces
ATA123079010	ATA123089010	M55609010	ATA123199010	ATA123499010	ATA123399010	ATA12391	ATA12392
ATA123078014	ATA123088014		ATA123198014				
40 pieces	20 pieces	5 pieces	20 pieces	10 pieces	20 pieces	20 pieces	10 pieces
ATA163079010	ATA163089010	M55609010	ATA123199010	ATA123499010	ATA123399010	ATA16391	ATA16392
ATA163078014	ATA163088014		ATA123198014				
20 pieces	10 pieces	5 pieces	20 pieces	10 pieces	20 pieces	20 pieces	10 pieces
ATA163079010	ATA163089010	M55609010	ATA123199010	ATA123499010	ATA123399010	ATA16391	ATA16392
ATA163078014	ATA163088014		ATA123198014				
20 pieces	10 pieces	5 pieces	20 pieces	10 pieces	20 pieces	20 pieces	10 pieces

Ceiling rose

- used with plinths: ATA12200 and ATA63000

Description	Pack qty.	Cat. ref.
pure white (9010)	6	ATA63059010

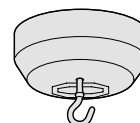


ATA63059

Ceiling rose DCL

- used with plinths: ATA12200, ATA12300 and ATA63000
 - delivered with connector and ceiling hook

Description	Pack qty.	Cat. ref.
pure white (9010)	6	ATA63069010

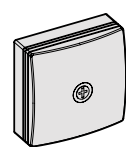


ATA63069

Delivery information: Base and lid together (lid opening with screwdriver) and 2 cables retainers/m (except 12x20).
Standard length: 2m, except for sizes: 12x20, 12x30, 16x30 and 6x30 (2,10 m). Other length on demand, max. 6 m.
Material: Rigid PVC. **Protection category:** IP 40, IK 07.

Note: The colour code indicates compatibility between accessories and trunkings.

		Base and lid	Adjustable external corner	Adjustable internal corner	Flat corner	End cap
		Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
	pure white	ATA125009010	ATA125039010	ATA125049010	ATA125059010	ATA125069010
	brown	ATA125008014	ATA125038014	ATA125048014	ATA125058014	ATA125068014
	packaging	48 m	20 pieces	20 pieces	20 pieces	20 pieces
	pure white	ATA125019010	ATA125039010	ATA125049010	ATA125059010	ATA125069010
	brown	ATA125018014	ATA125038014	ATA125049010	ATA125058014	ATA125068014
	packaging	48 m	20 pieces	20 pieces	20 pieces	20 pieces
	pure white	ATA125029010	ATA125039010	ATA125049010	ATA125059010	ATA125069010
	brown	ATA125028014	ATA125038014	ATA125048014	ATA125058014	ATA125068014
	packaging	48 m	20 pieces	20 pieces	20 pieces	20 pieces
	pure white	ATA205009010	ATA205039010	ATA205049010	ATA205059010	ATA205069010
	brown	ATA205008014	ATA205038014	ATA205048014	ATA205058014	ATA205068014
	packaging	32 m	20 pieces	20 pieces	20 pieces	20 pieces
	pure white	ATA205019010	ATA205039010	ATA205049010	ATA205059010	ATA205069010
	brown	ATA205018014	ATA205038014	ATA205048014	ATA205058014	ATA205068014
	packaging	32 m	20 pieces	20 pieces	20 pieces	20 pieces
	pure white	ATA205018014	ATA205039010	ATA205049010	ATA205059010	ATA205069010
	brown	ATA205028014	ATA205038014	ATA205048014	ATA205058014	ATA205068014
	packaging	32 m	20 pieces	20 pieces	20 pieces	20 pieces
	pure white	ATA207529010	ATA207539010	ATA207549010	ATA207559010	ATA207569010
	brown	ATA207528014	ATA207538014	ATA207548014	ATA207558014	ATA207568014
	packaging	24 m	20 pieces	20 pieces	20 pieces	20 pieces



ATA70759

Connection boxes 75 x 75 x 32 mm



Description	Pack qty.	Cat. ref.
pure white (9010)	10	ATA707599010
brown (8014)	10	ATA707598014

 
 
 
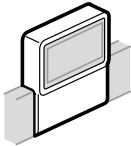
 
 
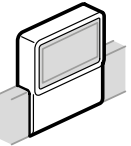


ATA71159

Connection boxes 115 x 115 x 52 mm

Description	Pack qty.	Cat. ref.
pure white (9010)	8	ATA711599010
brown (8014)	8	ATA711598014

 
Colours:  pure white (9010)
 brown (8014)

Joint cover	T, and deviation piece	Socket box 1-gang empty for Legrand outlet (1x45mm)	Socket box 2-gang empty for Legrand outlet (2x45mm)	Socket box 1-gang empty Alrea™ outlet (1x45mm)	Socket box 1-gang outlet for ateha	Socket box 2-gang outlet for ateha
						
Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
ATA125079010	ATA125089010	ATA125199010	ATA125499010	ATA125399010	ATA12591	ATA12592
ATA125078014	ATA125088014	ATA125198014				
20 pieces	10 pieces	20 pieces	10 pieces	20 pieces	20 pieces	10 pieces
ATA125079010	ATA125089010	ATA125199010	ATA125499010	ATA125399010	ATA12591	ATA12592
ATA125078014	ATA125088014	ATA125198014				
20 pieces	10 pieces	20 pieces	10 pieces	20 pieces	20 pieces	10 pieces
ATA125079010	ATA125089010	ATA125199010	ATA125499010	ATA125399010	ATA12591	ATA12592
ATA125078014	ATA125088014	ATA125198014				
20 pieces	10 pieces	20 pieces	10 pieces	20 pieces	20 pieces	10 pieces
ATA205079010	ATA205089010	ATA125199010	ATA125499010	ATA125399010	ATA20591	ATA20592
ATA205078014	ATA205088014	ATA125198014				
20 pieces	10 pieces	20 pieces	10 pieces	20 pieces	20 pieces	10 pieces
ATA205079010	ATA205089010	ATA125199010	ATA125499010	ATA125399010	ATA20591	ATA20592
ATA205078014	ATA205088014	ATA125198014				
20 pieces	10 pieces	20 pieces	10 pieces	20 pieces	20 pieces	10 pieces
ATA207579010	ATA207589010					
ATA207578014	ATA207588014					
20 pieces	10 pieces					

Universal boxes for socket

- 60 mm for ATA/LF
- dimensions: 90 x 90 x 42 mm

Description	Pack qty.	Cat. ref.
pure white (9010)	5	ATA806099010

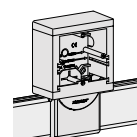


ATA80609

Universal boxes for socket

- 60 mm + adaptator ATA
- dimensions: 90 x 90 x 42 mm

Description	Pack qty.	Cat. ref.
pure white (9010)	5	ATA806199010




 



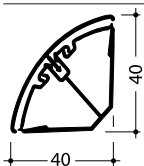
ATA80619

Delivery information: base, lid and cable retainers. Lid opening with screwdriver.

Standard length: 2.5 m. Other length on demand, max. 6 m.

 
 
Material: Rigid PVC. **Protection category:** IP 40, IK 07.

	Base and lid	Internal corner corner Flat corner	External corner	T piece	End cap
					
	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
pure white	EK4004009010	L27719010	L27729010	L27799010	L27739010
packaging	16 pieces	20 pieces	20 pieces	20 pieces	20 pieces



Colours: pure white (9010)

Joint cover	Deviation on	Adaptator
	ATA 12 x 20	ATA / SL with
	ATA 12 x 30	EK
	ATA 6 x 30	



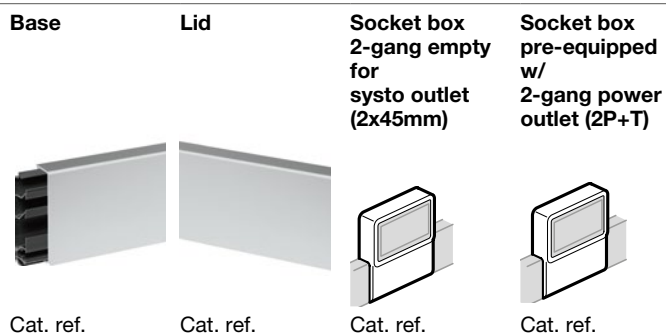
Cat. ref.	Cat. ref.	Cat. ref.
L27749010	L27809010	M55609010

20 pieces	15 pieces	5 pieces
-----------	-----------	----------

Delivery information: base pre-drilled and lid (opening with screwdriver) sold separately.





 
 

 
Standard length: 2m. Other length on demand, max. 6 m.

 
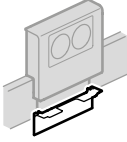
 
 

 
 
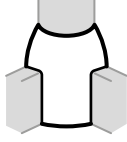
Material: Rigid PVC. **Protection category:** IP 40, IK 07.



	Base	Lid	Socket box 2-gang empty for systo outlet (2x45mm)	Socket box pre-equipped w/ 2-gang power outlet (2P+T)		
	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.		
		pure white (9010)	SL2005529010	SL200559039010	SL200559609010	
		graphite black (9011)	SL200551	SL2005529011	SL200559039011	SL200559609011
		alu		SL200552D1	SL20055903D1	SL20055960D1
		beech		SL200552D2		
		maple		SL200552D3		
		cherry		SL200552D4		
		oak		SL200552D5		
		sucupira		SL200552D6		
		with carpet border:				
		pure white (9010)		SL20055229010		
		with soft components:				
		pure white (9010)		SL20055219010		
		graphite black (9011)		SL20055219011		
		packaging	36 m	white/black: 36 m D1 to D6: 18 m	4 pieces	4 pieces
			pure white (9010)	SL2008029010	SL200809039010	SL200809609010
			graphite black (9011)	SL200801	SL2008029011	SL200809039011
		alu		SL200802D1	SL20080903D1	SL20080960D1
		beech		SL200802D2		
		maple		SL200802D3		
		cherry		SL200802D4		
		oak		SL200802D5		
		sucupira		SL200802D6		
		with carpet border:				
		pure white (9010)	SL200801LED	SL20080229010		
		with LED:				
		black		SL20080259011		
		alu		SL2008025D1		
		with soft components:				
		pure white (9010)		SL20080219010		
		graphite black (9011)		SL20080219011		
	packaging	36 m	white/black: 36 m D1 to D6 : 18 m LED: 18 m	4 pieces	4 pieces	
		pure white (9010)	SL2011529010	SL201159039010	SL201159609010	
		graphite black (9011)	SL201151	SL2011529011	SL201159039011	SL201159609011
		packaging	24 m	24 m	4 pieces	4 pieces

Colours:

 pure white (9010)	 decor aluminium (D1)	 decor maple (D3)	 decor oak (D5)
 graphite black (9011)	 decor beech (D2)	 decor cherry (D4)	 decor sucupira (D6)

Socket box universal for 60mm outlets	Box coupling	Adjustable internal corner	Adjustable external corner	Left and right end cap	T piece	Lid joint cover	EK adaptor
							
Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
SL200559019010	SL20055A9010	SL2005549010	SL2005539010	SL2005569010	SL2005589010	SL2005579010	SL20055819010
SL200559019011	SL20055A9011	SL2005549011	SL2005539011	SL2005569011	SL2005589011	SL2005579011	SL20055819011
SL20055901D1	SL20055AD1	SL200554D1	SL200553D1	SL200556D1	SL200558D1	SL200557D1	SL2005581D1
	SL20055AD2	SL200554D2	SL200553D2	SL200556D2		SL200557D2	
	SL20055AD3	SL200554D3	SL200553D3	SL200556D3		SL200557D3	
	SL20055AD4	SL200554D4	SL200553D3	SL200556D4		SL200557D4	
	SL20055AD5	SL200554D5	SL200553D5	SL200556D5		SL200557D5	
	SL20055AD6	SL200554D6	SL200553D6	SL200556D6		SL200557D6	
4 pieces	20 pieces	5 pieces	5 pieces	5 pieces	4 pieces	5 pieces	5 pieces
SL200809019010	SL20080A9010	SL2008049010	SL2008039010	SL2008069010	SL2008089010	SL2008079010	SL20080819010
SL200809019011	SL20080A9011	SL2008049011	SL2008039011	SL2008069011	SL2008089011	SL2008079011	SL20080819011
SL20080901D1	SL20080AD1	SL200804D1	SL200803D1	SL200806D1	SL200808D1	SL200807D1	SL2008081D1
	SL20080AD2	SL200804D2	SL200803D2	SL200806D2		SL200807D2	SL2008081D2
	SL20080AD3	SL200804D3	SL200803D3	SL200806D3		SL200807D3	SL2008081D3
	SL20080AD4	SL200804D4	SL200803D4	SL200806D4		SL200807D4	SL2008081D4
	SL20080AD5	SL200804D5	SL200803D5	SL200806D5		SL200807D5	SL2008081D5
	SL20080AD6	SL200804D6	SL200803D6	SL200806D6		SL200807D6	SL2008081D6
4 pieces	20 pieces	5 pieces	5 pieces	5 pieces	4 pieces	5 pieces	5 pieces
SL201159019010	SL20115A9010	SL2011549010	SL2011539010	SL2011569010	SL2011589010	SL2011579010	SL20115819010
SL201159019011	SL20115A9011	SL2011549011	SL2011539011	SL2011569011	SL2011589011	SL2011579011	SL20115819011
4 pieces	15 pieces	5 pieces	5 pieces	5 pieces	4 pieces	5 pieces	5 pieces

Description

The new tehalit.SL skirting trunking set with LED lighting enables the targeted use of lighting highlights combined with flexible cable management. The system is suitable for applications in indoor areas, e.g. in passageways and entrances.

Colours

- aluminium,
- black, RAL 9011



LED06WEISS

LED tube

- LED colour code: white approx. 6500 K
- light current per light: 2304 lm
- protection: IP68
- lighting angle: 120°
- power: 28.8 W
- voltage: 24 V
- number of LED: 360
- energy class: A

Description	Length	Cat. ref.
white	6 m	LED06WEISS



SL20080259011

Lid with 80mm height

- lid with integrated LED
- material: PVC

Description	Length	Cat. ref.
black color, RAL 9011	18 m	SL20080259011
aluminium decor	18 m	SL2008025D1



SL200801LED

Base with 80mm height

- specially for LED stripe

Description	Length	Cat. ref.
black	18 m	SL200801LED



SL200809LEDD1

Accessory box set LED for SL 20x80

- with transformer 30W
- the device carrier skirt **SL20080AXXXX** should be ordered separately

Description	Cat. ref.
aluminium	SL200809LEDD1



SL20080926D1

Accessory box SL 20x80 with Schuko socket and PIR

- Schuko socket
- 230V, 16A
 - **quickconnect** connection
 - increased touch protection

PIR

- angle of detection: 90° to 180°, manual setting without accessory
- brightness level setting: by push button or potentiometer
- the device carrier skirt **SL20080AXXXX** should be ordered separately

Description	Cat. ref.
aluminium	SL20080926D1

Transformer 30W/24 V for LED tube

- input voltage: 230 V/50 Hz
- output voltage: 24 V DC (2-gang)
- dimensions: 91 x 39.5 x 28.5 mm



Description

Cat. ref.

LEDTR030

transformer 30W/24V for LED tube

LEDTR030

Transformer 100 W/24 V for LED tube

- input voltage: 230 V/50 Hz
- output voltage: 24 V DC
- dimensions: 190 x 52 x 37 mm



Description

Cat. ref.

LEDTR100

transformer 100W/24V for LED tube

LEDTR100

Door crossing

- for new building or renovation
- height: 75 mm
- for a door, 2 door crossings are needed
- connection is done through standard ducts Ø 20 mm



Description

Cat. ref.

G6090SCHW

black

G6090SCHW

Connection box for tehalit.SL plinths

- offers the possibility to connect LV socket outlets and VLV data socket outlet.
- can be used as a storage box for a transformer (LED lighting)



Description

Cat. ref.

COL40110SET19010

white, RAL 9010

COL40110SET19010

aluminium

COL40110SET1ALU



AFOUTILPISTOLET

Glue guns for rigid glue

Description	Pack. qty	Cat. ref.
glue guns for rigid glue	6	AFOUTILPISTOLET
pure white glue cartridges, capacity 0.3 L	6	AFCOLLECART



AFCLOUSM118

Flat head nails

Description	Pack. qty	Cat. ref.
L = 18 mm, Ø = 2.5 mm	4 boxes	AFCLOUSM118
L = 25 mm, Ø = 2.5 mm	1 box	AFCLOUSM125



AFTH1520CLOUS

Nails

Description	Pack. qty	Cat. ref.
L = 20 mm, Ø = 1.5 mm	1 box	AFTH1520CLOUS
L = 25 mm, Ø = 1.5 mm	1 box	AFTH1525CLOUS
L = 30 mm, Ø = 1.5 mm	1 box	AFTH1530CLOUS



AFVISTC6023

Pack of 250 polyamide wall screws

- for fixing in BA 13 type hollow partition

Description	Pack. qty	Cat. ref.
L = 23 mm, Ø = 6 mm	4 pces	AFVISTC6023

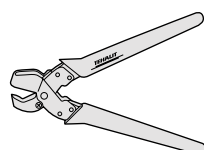


L5561

Cutting pliers

- to cut up mouldings to 45° and 90° up to 10 mms of depth

Description	Pack. qty	Cat. ref.
cutting pliers maximum length of cut 85 mm	1	L5561



L5562

Pliers for exit of cable

- to cut up the lateral partition of a trunking and to drill a cable hole

Description	Pack. qty	Cat. ref.
pliers for exit of cable Ø 20 mm	1	L5562



ATA99030

Cable retainers

- color: blue

Description	Pack. qty	Cat. ref.
pack of 50 cable retainers for ATA12300/12301, ATA16300/16301	10	ATA99030
pack of 30 cable retainers for ATA12500, ATA12501, ATA12502, ATA20500, ATA20501, ATA20502	15	ATA99050
pack of 20 cable retainers for ATA20752	15	ATA99075

 
Wires and cables diameter and section

for power and vlv data current

	approx. external Ø in mm	section in mm ²
wire: H 07 V		
1.5	2.8	6.2
2.5	3.4	9.1
4	3.9	11.9
6	4.7	17.3
telephone cable - STY1		
1 pair	3.8	11.3
2 pairs	4.9	18.9
3 pairs	5.2	21.2
4 pairs	5.7	25.5
5 pairs	6.1	29.2
data cable - Cat 5		
FTP 100 Ω 4 pairs	6.0	28.3
L 120 120 Ω 4 pairs	8 x 5	40.0
L 120 120 Ω 8 pairs	10.5 x 8	84.0
TV cable		
coax 75 Ω	7.0	38.5

	approx. external Ø in mm	section in mm ²
wire U1000R02V - H07RNF		
2 x 1.5	8.4	55.4
2 x 2.5	9.6	72.4
2 x 4	10.5	86.6
2 x 6	11.8	109.4
3 x 1.5	8.8	60.8
3 x 2.5	10.0	78.5
3 x 4	11.0	95.0
3 x 6	12.9	130.7
4 x 1.5	9.6	72.4
4 x 2.5	11.0	95.0
4 x 4	12.2	116.9
4 x 6	14.2	158.4
5 x 1.5	10.0	78.5
5 x 2.5	11.6	105.7
5 x 4	13.5	143.1
5 x 6	15.5	188.7

tehalit.atoha



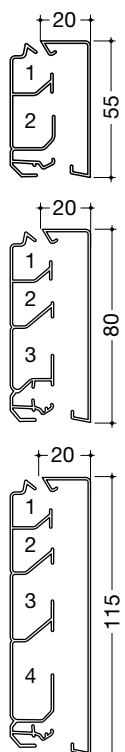
	compartments	dimensions A x B	wire number in mm ²				cable number		section by compartment in mm ²	
			1.5	2.5	4	6	3x25mm ²	Ø max.	nominal	useful*
references										
ATA12200	1	13 x 24	18	13	9	6	1	11.5	226	113
ATA12201	1 2	13 x 24	7 7	5 5	3 3	2 2	0 0	7.5 7.5	90 90	45 45
ATA12300	1	13 x 32	24	19	15	10	2	11.5	281	141
ATA12301	1 2	13 x 32	10 10	8 8	6 6	4 4	1 1	11.5 11.5	128 128	64 64
ATA12500	1	13 x 52	44	36	23	16	4	11.5	551	276
ATA12501	1 2	13 x 52	29 11	24 8	15 5	11 4	3 1	11.5 11.5	313 127	157 64
ATA12502	1 2 3	13 x 52	11 15 11	8 12 8	5 7 5	4 6 4	1 1 1	11.5 11.5 11.5	128 162 128	64 81 64
ATA16300	1	16 x 32	32	26	17	12	3	12.5	372	186
ATA16301	1 2	16 x 32	14 14	11 11	7 7	5 5	1 1	12.5 12.5	160 160	80 80
ATA20500	1	20 x 52	69	51	37	30	6	16.5	817	409
ATA20501	1 2	20 x 52	46 19	34 14	25 9	16 6	4 1	16.5 16.5	546 227	273 114
ATA20502	1 2 3	20 x 52	19 23 19	14 17 14	9 12 9	6 9 6	1 1 1	16.5 16.5 16.5	227 274 227	114 137 114
ATA20752	1 2 3	20 x 74	19 51 19	14 43 14	9 32 9	6 21 6	1 5 1	16.5 16.5 16.5	227 613 227	114 307 114

skirting systems for corners EK references

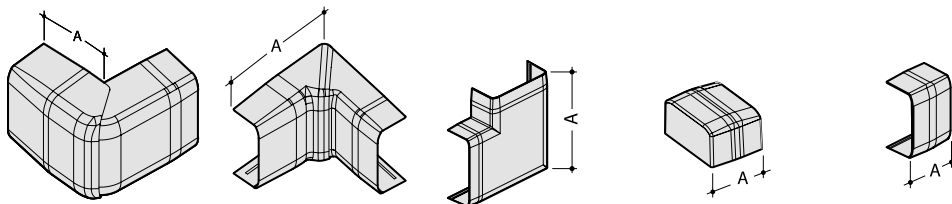
EK400400	1 2	40 x 40	24 24	16 16	12 12	8 8	2 2	16 16	300 300	150 150
-----------------	--------	---------	----------	----------	----------	--------	--------	----------	------------	------------

* section acting as base of calculation to define the countenance according to the different section of cables.

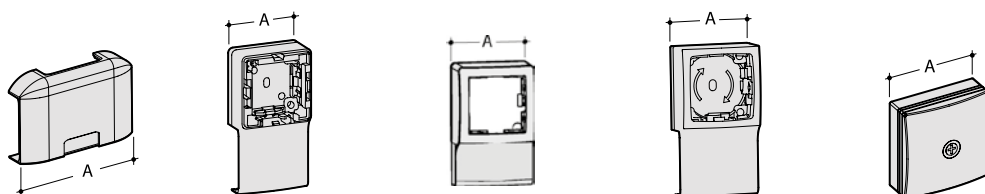
tehalit.SL



	Compartments	wire				cable		
		1.5 mm ²	2.5 mm ²	4 mm ²	6 mm ²	3 x 1.5 mm ²	3 x 2.5 mm ²	Ø max
SL20055	1 2	14 30	11 21	7 15	4 9	2 3	1 2	15 15
SL20080	1 2 3	14 23 35	11 14 21	8 10 15	6 7 11	1 2 4	1 2 2	15 15 15
SL20115	1 2 3 4	14 18 35 52	11 14 27 33	7 9 19 23	5 6 12 15	1 2 5 5	1 2 3 3	15 15 15 15



profile types	external corner size in mm	internal corner size in mm	flat corner size in mm	end cap size in mm	joint cover size in mm
ATA12200/12201	26.5	48	50	24	24
ATA12300/12301	26.5	48	58	24	24
ATA12500/12501/12502	26.5	48	78	24	24
ATA16300/16301	26.5	49.5	58	24	24
ATA20500/20501/20502	26.5	54	78	24	24
ATA20752	26.5	54	100	24	24



profile types	T and deviation piece size in mm	box for socket Legrand equipment protrusion double size in mm	box for socket simple Alréa™ size in mm	box for socket Profil 2™ size in mm	connection box size in mm	
ATA12200/12201	72	66	128	62	66	-
ATA12300/12301	80	66	128	62	66	-
ATA12500/12501/12502	102	66	128	62	66	-
ATA16300/16301	85	66	128	62	66	-
ATA20500/20501/20502	114	66	128	62	66	-
ATA20752	140	66	128	62	66	-
ATA70759	-	-	-	-	-	77
ATA71159	-	-	-	-	-	114