

Line distribution

tehalit.lifea trunking ranges are suitable with all kind of conductor controls and cables in housing and tertiary premises thanks to their several types of profiles.



tehalit.lifea	9.2
tehalit.FB	9.10
tehalit.CLM	9.12
Accessories	9.14
tehalit.LFR	9.15
Self sticking mini trunking	9.16
Technical guide	9.17





Line distribution

 
 
 

 

PVC tehalit.lifea from 10 to 30 mm depth

Delivery information: Base pre-drilled (except LF100100), lid, coupling pieces, cable retainers (from 60 mm on width). Lid (opening with screwdriver)
Standard length: 2m, other lengths on demand, max. 6 m.
Material: Rigid PVC. **Protection category:** IP 40, IK 07.

		Full trunking Base and lid		Internal cover*	External corner*
		Cat. ref.		Cat. ref.	Cat. ref.
	pure white (9010)	LF1001009010			
	brown (8014)	LF1001008014			
	packaging	84 m			
	pure white (9010)	LF1501509010			
	brown (8014)	LF1501508014			
	black (9011)	LF1501509011			
	packaging	44 m			
	pure white (9010)	LF2002009010			
	brown (8014)	LF2002008014			
	packaging	36 m			
	pure white	LFF2003509010		M61419010	M61429010
	brown (8014)	LFF2003508014		M61418014	M61428014
	packaging	40 m		20 pieces	20 pieces
	pure white (9010)	LFF2003609010		M61419010	M61429010
	brown (8014)	LFF2003608014		M61418014	M61428014
	packaging	40 m		20 pieces	20 pieces
	pure white (9010)	LFF3003009010	delivered with 2 coupling pieces	M59619010	M59629010
	grey (7030)	LFF3003007030		M59618014	M59627030
	packaging	56 m		5 pieces	5 pieces
	pure white (9010)	LFF3004509010	delivered with 2 coupling pieces	M61819010	M61829010
	grey (7030)	LFF3004507030		M61817030	M61827030
	packaging	32 m		8 pieces	8 pieces
	pure white (9010)	LFF3006009010	delivered with 4 cable retainers M7239 and 2 coupling pieces	LFF300649010	LFF300639010
	grey (7030)	LFF3006007030		LFF300647030	LFF300637030
	packaging	32 m		5 pieces	5 pieces

* Adjustable corners only for LFF300600

Colours:  pure white (9010)  grey (7030)  black (9011)
 brown (8014)

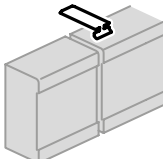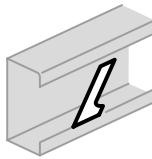Flat corner	End caps*	Joint cover lid	Joint cover base	T piece	Cable retainer
					
Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
	M61139010				
	M61138014				
	5 pieces				
	M612390101				
	M61238014				
	5 pieces				
M61459010	M61439010			M61469010	
M61458014	M61438014			M61468014	
20 pieces	20 pieces			10 pieces	
M61459010	M61439010			M61469010	
M61458014	M61438014			M61468014	
20 pieces	20 pieces			10 pieces	
M59659010	M59639010		LFF60J9010	M59669010	
M59657030	M59637030			M59667030	
5 pieces	5 pieces		10 pieces	5 pieces	
M61859010	M61839010		LFF60J9010	M61869010	
M61857030	M61837030			M61867030	
5 pieces	5 pieces		10 pieces	8 pieces	
LFF300659010	LFF600669010	LFF600679010	LFF60J9010	M53969010	
LFF300657030	LFF600667030			M53967030	
					M7239
5 pieces	10 pieces	10 pieces	10 pieces	10 pieces	10 pieces

Line distribution


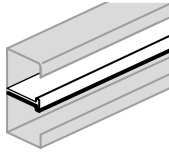
 
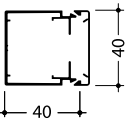
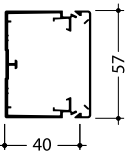
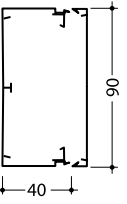
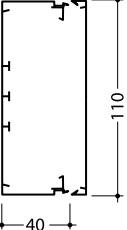
PVC tehalit.lifea 40 mm depth



Delivery information: Base pre-drilled, lid and cable retainer (except LF400400). Lid (opening with screwdriver).

 
 
 
 
 
 

Standard length: 2m, other lengths on demand, max. 6 m.



Material: Rigid PVC. **Protection category:** IP 40, IK 07.

 
 

 
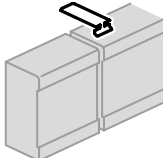
 
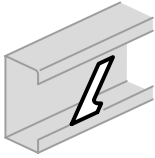
		Full trunking Base and lid		Partition	Adjustable internal corner*
					
		Cat. ref.		Cat. ref.	Cat. ref.
	pure white (9010)	LFF4004009010	delivered with 2 coupling pieces		M58019010
	grey (7030)	LFF4004007030			M58017030
	packaging	32 m			5 pieces
	pure white (9010)	LFF4006009010	delivered with 4 cable retainers		LFF400649010
	grey (7030)	LFF4006007030	M7239 and 2 coupling pieces		LFF400647030
	packaging	24 m		M2024 50 m	5 pieces
	pure white (9010)	LFF4009009010	delivered with 4 cable retainers		LFF400949010
	grey (7030)	LFF4009007030	M7248 and 2 coupling pieces		LFF400947030
	packaging	24 m		M2024 50 m	5 pieces
	pure white	LFF4011009010	delivered with 4 cable retainers		LFF401149010
	grey (7030)	LFF4011007030	M7249 and 2 coupling pieces		LFF401149010
	packaging	20 m		M2024 50 m	5 pieces

* except for LFF400400

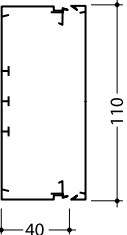BS wiring accessories for LFF4011009010


	Kit 1 gang	1 gang support	1 gang insulation	Kit 2 gang	2 gang support	2 gang insulation
						
	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
	pure white (9010)	LFF71BZ1109010	LFF71B1109010	LFF79B1	LFF72BZ1109010	LFF72B1109010
	packaging	5 pieces	5 pieces	5 pieces	5 pieces	5 pieces

Colours:  pure white (9010)
 grey (7030)

Ajustable external corner *	Flat corner	End caps*	Joint cover lid	Joint cover base	T piece	Cable retainer
						
Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
M58029010	M58059010	M58039010		LFF60J9010	M58069010	
M58027030	M58057030	M58037030			M58067030	
8 pieces	5 pieces	5 pieces		10 pieces	10 pieces	
LFF400639010	LFF400659010	LFF600669010	LFF600679010	LFF60J9010	M54069010	
LFF400637030	LFF400657030	LFF600667030			M54067030	
						M7239
5 pieces	5 pieces	10 pieces	10 pieces	10 pieces	10 pieces	10 pieces
LFF400939010	LFF400959010	LFF600969010	LFF600979010	LFF60J9010	M54569010	
LFF400937030	LFF400957030	LFF600967030			M54567030	
						M7248
5 pieces	5 pieces	10 pieces	10 pieces	10 pieces	5 pieces	10 pieces
LFF401139010	LFF401159010	LFF601169010	LFF601179010	LFF60J9010	M54169010	
LFF401137030	LFF401157030	LFF601167030			M54167030	
						M7249
5 pieces	5 pieces	10 pieces	10 pieces	10 pieces	10 pieces	10 pieces

Frames for wiring accessories 45x45 support

Description	Colour	Pack qty.	Cat. ref. 45 x 45	Cat. ref. center distance 60 mm
for LFF40090	pure white	10	LFF71H0909010	LFF71U0909010
for LFF40110	pure white	10	LFF71H1109010	LFF71U1109010

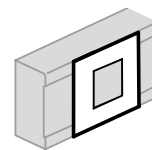

Back boxes for wiring accessories 45x45 supports


Description	Colour	Pack qty.	Cat. ref.
for support frame LFF71H090	pure white	4 sets of 10	LFF71H0999010
for support frame LFF71H110	pure white	4 sets of 10	LFF71H1199010



LFF71H099

Insulation boxes

Description	Colour	Pack qty.	Cat. ref.
for 45 x 45 support frame	black	10	LFF79H
for 60 mm support frame	black	10	LFF79U

 

LFF79U


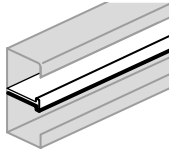
 
 
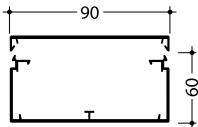
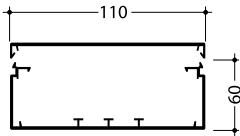
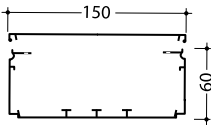
 
 
Line distribution

PVC tehalit.lifea 60 mm depth

 
 
 
 
 
 

Delivery information: Base pre-drilled, lid and cable retainer. Lid (opening with screwdriver).



Standard length: 2m, other lengths on demand, max. 6 m.

 
 

 
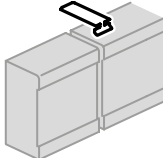
 
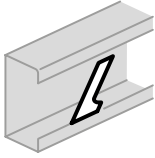
Material: Rigid PVC. **Protection category:** IP 40, IK 07.

		Full trunking Base and lid		Partition	Adjustable internal corner*
					
		Cat. ref.		Cat. ref.	Cat. ref.
	pure white (9010)	LFF6006009010	delivered with 4 cable retainers		LFF600649010
	grey (7030)	LFF6006007030	M7239		LFF600647030
	packaging	16 m	and 2 coupling pieces		8 pieces
	pure white (9010)	LFF6009009010	delivered with 4 cable retainers		LFF600949010
	grey (7030)	LFF6009007030	M7248		LFF600947030
	packaging	16 m	and 2 coupling pieces	M2026	5 pieces
				50 m	
	pure white (9010)	LFF6011009010	delivered with 4 cable retainers		LFF601149010
	grey (7030)	LFF6011007030	M7249		LFF601147030
	packaging	16 m	and 2 coupling pieces	M2026	5 pieces
				50 m	
	pure white	LFF6015009010	delivered with 4 cable retainers		M55219010
	grey (7030)	LFF6015007030	M7250		M55217030
	packaging	8 m	and 2 coupling pieces	M2026	5 pieces
				50 m	
	pure white	LFF6019009010	delivered with 4 cable retainers		M55319010
	grey (7030)	LFF6019007030	M7251		M55317030
	packaging	8 m	and 2 coupling pieces	M2026	8 pieces
				50 m	
	pure white	LFF6023009010	delivered with 4 cable retainers		M55419010
	grey (7030)	LFF6023007030	M7252		M55417030
	packaging	8 m	and 2 coupling pieces	M2026	8 pieces
				50 m	

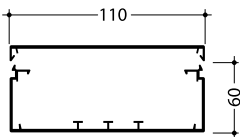** except for LFF601500, LFF601900 and LFF602300


BS wiring accessories for LFF601100 9010	Kit 1 gang	1 gang support	1 gang insulation	Kit 2 gang	2 gang support	2 gang insulation
						
	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
	pure white (9010)	LFF71BZ1109010	LFF71B1109010	LFF79B1	LFF72BZ1109010	LFF72B1109010
	packaging	5 pieces	5 pieces	5 pieces	5 pieces	5 pieces

Colours:  pure white (9010)
 grey (7030)

Ajustable external corner *	Flat corner	End caps*	Joint cover lid	Joint cover base	T piece	Cable retainer
						
Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
LFF600639010	LFF600659010	LFF600669010	LFF600679010	LFF60J9010	M54469010	
LFF600637030	LFF600657030	LFF600667030			M54467030	M7239
5 pieces	5 pieces	10 pieces	10 pieces	10 pieces	5 pieces	10 pieces
LFF600939010	LFF600959010	LFF600969010	LFF600979010	LFF60J9010	M54669010	
LFF600937030	LFF600957030	LFF600967030			M54667030	M7248
5 pieces	5 pieces	10 pieces	10 pieces	10 pieces	8 pieces	10 pieces
LFF601139010	LFF601159010	LFF601169010	LFF601179010	LFF60J9010	M55069010	
LFF601137030	LFF601157030	LFF601167030			M55067030	M7249
5 pieces	5 pieces	10 pieces	10 pieces	10 pieces	5 pieces	10 pieces
M55229010	M55259010	M55239010		LFF60J9010	M55269010	
M55227030	M55257030	M55237030			M55267030	M7250
5 pieces	12 pieces	5 pieces		10 pieces	10 pieces	20 pieces
M55329010	M55359010	M55339010		LFF60J9010	M55369010	
M55327030	M55357030	M55337030			M55367030	M7251
8 pieces	10 pieces	5 pieces		10 pieces	8 pieces	20 pieces
M55429010	M55459010	M55439010		LFF60J9010	M55469010	
M55427030	M55457030	M55437030			M55467030	M7252
5 pieces	6 pieces	5 pieces		10 pieces	8 pieces	20 pieces

Frames for wiring accessories 45x45 supports

Description	Colour	Pack qty.	Cat. ref. 45 x 45	Cat. ref. center distance 60 mm
for LFF60090	pure white	10	LFF71H0909010	LFF71U0909010
for LFF60110	pure white	10	LFF71H1109010	LFF71U1109010

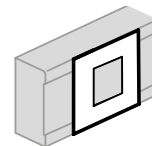

Back boxes for wiring accessories 45x45 supports


Description	Colour	Pack qty.	Cat. ref.
for support frame LFF71H090	pure white	4 sets of 10	LFF71H0999010
for support frame LFF71H110	pure white	4 sets of 10	LFF71H1199010



LFF71H099

Insulation boxes

Description	Colour	Pack qty.	Cat. ref.
for 45 x 45 support frame	black	10	LFF79H
for 60 mm support frame	black	10	LFF79U

 

LFF79U

Line distribution

 
 
 


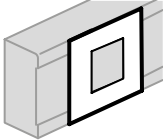
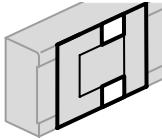
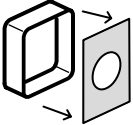
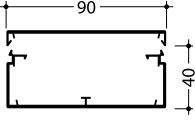
 
 

PVC tehalit.lifea trunking with wiring accessories support



 

 
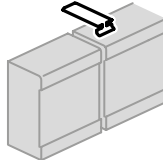
 
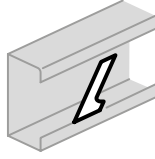
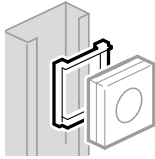
Delivery information: Base pre-drilled, lid and cable retainer. Lid (opening with screwdriver).

Standard length: 2m, other lengths on demand, max. 6 m.

Material: Rigid PVC. **Protection category:** IP 40, IK 07.

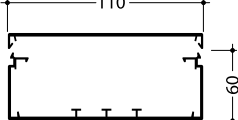		Full trunking Base and lid cable retainers	Partition	Adjustable internal corner*	Ajustable external corner
	pure white (9010)	LFF4009009010	M2024	LFF400949010	LFF400939010
	grey (7030)	LFF4009007030		LFF400947030	LFF400937030
	packaging	24 m	50 m	5 pieces	5 pieces
	pure white (9010)	LFF4011009010	M2024	LFF401149010	LFF401139010
	grey (7030)	LFF4011007030		LFF401147030	LFF401137030
	packaging	20 m	50 m	5 pieces	5 pieces
	pure white (9010)	LFF6009009010	M2026	LFF600949010	LFF600939010
	grey (7030)	LFF6009007030		LFF600947030	LFF600937030
	packaging	16 m	50 m	5 pieces	5 pieces
	pure white	LFF6011009010	M2026	LFF601149010	LFF601139010
	grey (7030)	LFF6011007030		LFF601147030	LFF601137030
	packaging	12 m	50 m	5 pieces	5 pieces
		Full trunking Base and lid cable retainers	Frame 45x45 support	Extension for frame 45x45 support	Insulation box for frame 45x45 support
					
		Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
	pure white	LFF4009009010	LFF71H0909010	LFF71H0999010	LFF79H
	packaging	24 m	10 pieces	4 packs of 10	10 pieces
	pure white	LFF4011009010	LFF71H1109010	LFF71H1199010	LFF79H
	packaging	20 m	10 pieces	4 packs of 10	10 pieces
	pure white	LFF6009009010	LFF71H0909010	LFF71H0999010	LFF79H
	packaging	16 m	10 pieces	4 packs of 10	10 pieces
	pure white	LFF6011009010	LFF71H1109010	LFF71H0999010	LFF79H
	packaging	12 m	10 pieces	4 packs of 10	10 pieces

Colours: pure white (9010)
 grey (7030)

Flat corner	End caps	Joint cover lid	Joint cover base	T piece	Cable retainer	Frame for vertical mounting
						
Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
LFF400959010	LFF600969010	LFF600979010	LFF60J9010	M54569010		
LFF400957030	LFF600967030			M54567030	M7248	
						L4770
5 pieces	10 pieces	10 pieces	10 pieces	5 pieces	10 pieces	5 pieces
LFF401159010	LFF601169010	LFF601179010	LFF60J9010	M54169010		
LFF401157030	LFF601167030			M54167030	M7249	
						L4770
5 pieces	10 pieces	10 pieces	10 pieces	5 pieces	10 pieces	5 pieces
LFF600959010	LFF600969010	LFF600979010	LFF60J9010	M54669010		
LFF600957030	LFF600967030			M54667030	M7248	
						L4770
5 pieces	10 pieces	10 pieces	10 pieces	10 pieces	10 pieces	5 pieces
LFF601159010	LFF601169010	LFF601179010	LFF60J9010	M55069010		
LFF601157030	LFF601167030			M55067030	M7249	
						L4770
5 pieces	10 pieces	10 pieces	10 pieces	8 pieces	10 pieces	5 pieces
LFF71H0909010 + 2x LFF71H0993010	LFF71H0909010 + 4x LFF71H0993010	LFF71H0909010 + 6x LFF71H0993010	LFF71U0909010	LFF79U		
			10 pieces	10 pieces		
LFF71H1109010 + 2x LFF71H1193010	LFF71H1109010 + 4x LFF71H1193010	LFF71H1109010 + 6x LFF71H1193010	LFF71U1109010	LFF79U		
			10 pieces	10 pieces		
LFF71H0909010 + 2x LFF71H0993010	LFF71H0909010 + 4x LFF71H0993010	LFF71H0909010 + 6x LFF71H0993010	LFF71U0909010	LFF79U		
			10 pieces	10 pieces		
LFF71H1109010 + 2x LFF71H1193010	LFF71H1109010 + 4x LFF71H1193010	LFF71H1109010 + 6x LFF71H1193010	LFF71U1109010	LFF79U	LFF71Z1109010	
			10 pieces	10 pieces	4 pieces	


 
 
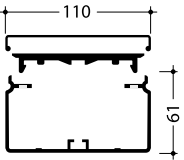
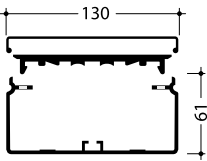
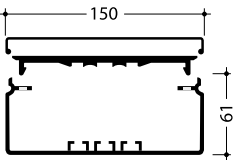
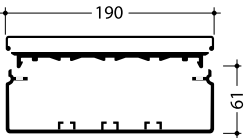
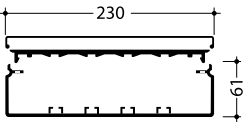
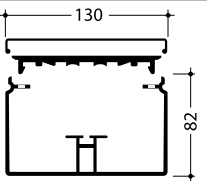

Line distribution



PVC tehalit.FB for industrial application


 
 
 
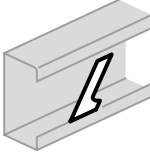
Delivery information: Base pre-drilled, lid and cable retainer (2pcs per meter). Lid (opening with screwdriver).

Standard length: 2m, other lengths on demand, max. 6 m.

Material: Rigid PVC. **Protection category:** IP 40, IK 07.

		Full trunking Base and lid		Partition	Internal corner
					
		Cat. ref.		Cat. ref.	Cat. ref.
	pure white (9010)	FB6011009010	delivered with 4 cable retainers M5280		M55019010
	grey (7030)	FB6011007030			
	packaging	16 m		M1346	
	pure white (9010)	FB6013009010	delivered with 4 cable retainers M5281		M55119010
	grey (7030)	FB6013007030			M55117030
	packaging	12 m		M1346	
	pure white (9010)	FB6015009010	delivered with 4 cable retainers M5282		M55219010
	grey (7030)	FB6015007030			M55217030
	packaging	12 m		M1346	
	pure white	FB6019009010	delivered with 4 cable retainers M5283		M55319010
	grey (7030)	FB6019007030			M55317030
	packaging	8 m		M1346	8 pieces
	pure white (9010)	FB6023009010	delivered with 4 cable retainers M5284		M55419010
	grey (7030)	FB6023007030			M55417030
	packaging	12 m		M1346	8 pieces
	pure white (9010)	FB80130090101	delivered with 4 cable retainers M5281		L87619010
	grey (7030)	FB80130070301			L87617030
	packaging	16 m		M1346	6 pieces
	pure white (9010)	FB9923009010	delivered with 4 cable retainers M5284		L96819010
	grey (7030)	FB9923007030			L96817030
	packaging	6 m		M1629	1 piece

Colours:  pure white (9010)
 grey (7030)

External corner	Flat corner	T piece	End caps	Cable retainer
				
Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
M55029010	M55059010	M55069010	M55039010	
M55027030	M55057030	M55067030	M55037030	
				M5280
5 pieces	6 pieces	5 pieces	5 pieces	50 pieces
M55129010	M55159010	M55169010	M55139010	
M55127030	M55157030	M55167030	M55137030	
				M5281
8 pieces	8 pieces	14 pieces	5 pieces	50 pieces
M55229010	M55259010	M55269010	M55239010	
M55227030	M55257030	M55267030	M55237030	
				M5282
5 pieces	12 pieces	10 pieces	5 pieces	50 pieces
M55329010	M55359010	M55369010	M55339010	
M55327030	M55357030	M55367030	M55339010	
				M5283
8 pieces	10 pieces	8 pieces	5 pieces	50 pieces
M55429010	M55459010	M55469010	M55439010	
M55427030	M55457030	M55467030	M55437030	
				M5284
5 pieces	6 pieces	8 pieces	5 pieces	50 pieces
L87629010	L87659010		M53039010	
L87627030	L87657030		M53037030	
				M5281
7 pieces	8 pieces		6 pieces	50 pieces
L96829010	L96859010		M58339010	
L96827030	L96857030		M58337030	
				M5284
2 pieces	1 piece		6 pieces	50 pieces


 
 

 
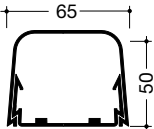
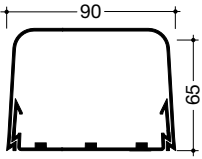
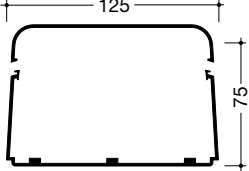
Line distribution


PVC tehalit.CLM

 
 
 
 

 
 
Delivery information: Pre-drilled base with lugs for clip, lid around the trunking


Standard length: 2m

Material: Rigid PVC.

		Full trunking Base and lid	Internal corner	External corner	Flat corner
					
		Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
	pure white (9010)	CLM30035	CLM300354	CLM300353	CLM300355
	packaging	52 m	10 pieces	10 pieces	10 pieces
	pure white (9010)	CLMU50065	CLM500654	CLM500653	CLM500655
	packaging	24 m	10 pieces	10 pieces	10 pieces
	pure white (9010)	CLMU65090	CLM650904	CLM650903	CLM650905
	packaging	16 m	5 pieces	5 pieces	5 pieces
	pure white (9010)	CLM75125	CLM751254	CLM751253	CLM751255
	packaging	10 m	1 piece	1 piece	1 piece

Colours:  pure white (9010)

Flat corner	Wall derivation	Joint cover lid	T piece	Wall joint	Reducer	Cable retainer
						
Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.	Cat. ref.
CLM300356	CLM3003561	CLM300357		CLM300359		
10 pieces	10 pieces	10 pieces		10 pieces		
CLM500656	CLM5006561	CLM500657	CLM500658	CLM500659		
10 pieces	10 pieces	10 pieces	5 pieces	10 pieces		
CLM650906	CLM6509061	CLM650907	CLM650908	CLM650908	CLM6509062	
10 pieces	5 pieces	5 pieces	5 pieces	10 pieces	5 pieces	
CLM751256	CLM7512561	CLM751257	CLM751258	CLM751259	CLM7512562	CLM125
1 piece	1 piece	1 piece	1 piece	1 piece	1 piece	15 pieces

 

L5111

Junction box

- IP54

Description	Pack qty.	Cat. ref.
halogen free junction box	10	L5111



M5159/1/2

Spacers

Description	Pack qty.	Cat. ref.
12 mm height, ø 25 mm	50	M51592
20 mm height, ø 25 mm	50	M5159



M5164

Set ring

Description	Pack qty.	Cat. ref.
for M3 - M5	100	M5164




L5804

Sound proof barrier

- 15 twisted mineral fibers
- attenuation: around 40 dB
- fireproof, class M1

Description	Pack qty.	Cat. ref.
length 300 mm, ø 30 mm	1	L5804

 


L5561

Cutter plier

- to cut trunking up to 20 x 35 at 45° or 90°

Description	Pack qty.	Cat. ref.
cutter plier, length: up to 85 mm	1	L5561

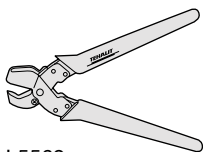

L5562

Notching plier


- to cut out a ø 20mm notch on the trunking side

Description	Pack qty.	Cat. ref.
notching plier for ø 20mm cable outlet	1	L5562


Delivery information: Pre-drilled base and lid complete with self adhesive tape
Standard length: 20 meter roll
Material: Rigid PVC.

Colour:  pure white (9010)

 
Full trunking
Base and lid



	Cat. ref.	Trunking volume
pure white (9010)	LFR701209010T2	1 phone cable 4 pairs STY 1
packaging	20 m	

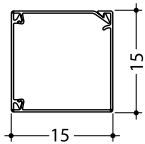


pure white (9010)	LFR1501509010T2	2 phone cables 4 pairs STY 1 1 cable 3 x 2.5 mm ²
packaging	20 m	

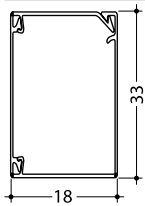

pure white (9010)	LFR2003509010T2	4 phone cables 4 pairs STY 1 3 cables 3 x 2.5 mm ²
packaging	20 m	

Cutter plier

 - to cut trunking up to 20 x 35 at 45° or 90°




Description	Pack qty.	Cat. ref.
cutter plier, length: up to 85 mm	1	L5561

L5561

Notching plier

- to cut out a ø 20mm notch on the trunking side

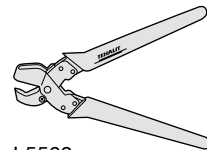

Description	Pack qty.	Cat. ref.
notching plier for ø 20mm cable outlet	1	L5562

L5562

Line distribution

self-sticking mini trunking

Delivery information: base with double-face joining tape
Standard length: 2m
Material: Rigid PVC.

Colours:

 
 
 
 


transparent (**TRAN**)
 cream white (**9001**)

Self-sticking Cable guide


Base



		Cat. ref.	Trunking volume
	transparent (TRAN)	M1647TRAN	for 1 cable ø 4,5 to 6 m
	white (9001)	M16479001	
	packaging	150 m	
	transparent (TRAN)	M1648TRAN	for 1 cable ø 5,5 to 7 m
	white (9001)	M16489001	
	packaging	150 m	
	transparent (TRAN)	M1673TRAN	for 1 cable ø 6,5 to 8 m
	white (9001)	M16739001	
	packaging	150 m	
	transparent (TRAN)	M1659TRAN	for 1 cable ø 7,5 to 10 m
	white (9001)	M16599001	
	packaging	150 m	

Delivery information: base with double-face joining tape and lid
Standard length: 2m
Material: Rigid PVC.

 Colours:







pure white (**9010**)

Self-sticking Mini trunking

    Base



		Cat. ref.	Trunking volume
	pure white (9010)	LF1001009010A	for 1 cable ø 7
	packaging	84 m	
	pure white (9010)	LFC100159010A	for 2 cables ø 6
	packaging	148 m	
	pure white (9010)	LF1501509010A	for 1 cable ø 10
	packaging	88 m	
	pure white (9010)	LF2002009010A	for 1 cable ø 12
	packaging	54 m	

tehalit.lifea:


Wires, cables diameter and section for power and vlv data current

	approx. external diameter in mm	cross section in mm ²
wire: H 07 V		
1.5	2.8	6.2
2.5	3.4	9.1
4	3.9	11.9
6	4.7	17.3
telephone cable - STY1		
1 pair	3.8	11.3
2 pairs	4.9	18.9
3 pairs	5.2	21.2
4 pairs	5.7	25.5
5 pairs	6.1	29.2
data cable - Cat 5		
FTP 100 Ω 4 pairs	6.0	28.3
L 120 120 Ω 4 pairs	8 x 5	40.0
L 120 120 Ω 8 pairs	10.5 x 8	84.0
tv cable		
feeder 75 Ω	7.0	38.5

	approx. external diameter in mm	cross section in mm ²
cable U1000R02V - H07RNF		
2 x 1.5	8.4	55.4
2 x 2.5	9.6	72.4
2 x 4	10.5	86.6
2 x 6	11.8	109.4
3 x 1.5	8.8	60.8
3 x 2.5	10.0	78.5
3 x 4	11.0	95.0
3 x 6	12.9	130.7
4 x 1.5	9.6	72.4
4 x 2.5	11.0	95.0
4 x 4	12.2	116.9
4 x 6	14.2	158.4
5 x 1.5	10.0	78.5
5 x 2.5	11.6	105.7
5 x 6	13.5	143.1
5 x 4	15.5	188.7

Trunking volume LF, LFF, FB

tehalit.lifea trunking

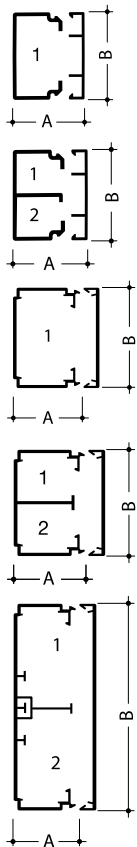


	partition number	size A x B	nominal cross section in mm ²	effective cross section in mm ²	maximum ø in mm	cable aera 3 x 2.5 mm ²
references						
LF150150	1	15 x 15	150	75	10	1
LF200200	1	20 x 19	228	114	12	1
LFF200350	1	20 x 33	440	220	15	2
LFF200360	1	20 x 33	210	105	10	1
	2		210	105	10	1
LFF300300	1	30 x 30	620	310	15	4
LFF300450	1	30 x 45	970	485	25	6
LFF300600	1	30 x 57	1250	625	25	8
LFF400400	1	40 x 40	1200	600	23	8
LFF400600	1	40 x 57	1700	850	29	11
LFF400610	1	40 x 57	830	415	15	5
	2		830	415	15	5
LFF400900	1	40 x 90	2650	1325	32	17
LFF400900 + M2024	1	40 x 90	1300	650	24	8
	2		1300	650	24	8
LFF401100	1	40 x 110	3250	1625	32	21
LFF401100 + M2024 ⁽¹⁾	1	40 x 110	1600	800	32	10
	2		1600	800	32	10
LFF600600	1	60 x 57	2860	1430	54	18
LFF600900	1	60 x 90	4550	2275	54	29
LFF600900 + M2026	1	60 x 90	2200	1100	29	14
	2		2200	1100	29	14
LFF601100	1	60 x 110	5500	2750	54	35
LFF601100 + M2026 ⁽¹⁾	1	60 x 110	2600	1300	29	19
	2		2600	1300	29	19
LFF601500 + M2026 ⁽¹⁾	1	61 x 150	3600	1790	54	24
	2		3600	1790	54	24
LFF601900 + M2026 ⁽¹⁾	1	61 x 190	4590	2280	54	29
	2		4590	2280	54	29
LFF602300 + M2026 ⁽¹⁾	1	61 x 230	5610	2790	54	35
	2		5610	2790	54	35
references						
FB601100	1	61 x 110	4680	2340	54	30
FB601300	1	61 x 130	5580	2790	54	36
FB601500	1	61 x 150	6450	3225	54	41
FB601900	1	61 x 190	8280	4140	54	53
FB602300	1	61 x 230	9800	4900	54	62
FB801300	1	82 x 130	7700	3850		49
FB992300	1	100 x 230	18500	9250		118


* cross-section to be used to determinate the cable area

⁽¹⁾ cable area with the partition in the middle


tehalit.FB trunking

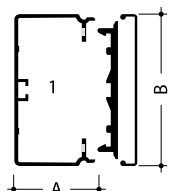


LFF

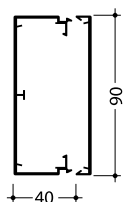


		with wiring accessories			without wiring accessories
		45 x 45	center distance 60	CEE 17	
LFF400900					
number of cables	power current 3 x 2.5 mm ²	area 1 ⁽¹⁾	10	8	17
		area 1/2 ⁽²⁾	5/5	4/4	8/8
	vlv data current L 120 - 4 pairs	area 1	24	19	35
		area 1/2	12/12	9/9	17/17
nominal cross section/ effective* per area		area 1	1850/925	1420/710	2650/1325
		area 1/2	900/450	685/342	1300/650

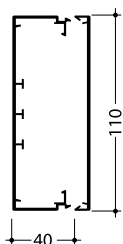

LFF401100					
number of cables	power current 3 x 2.5 mm ²	area 1	14	11	21
		area 1/2	6/6	5/5	10/10
	vlv data current L 120 - 4 pairs	area 1	31	26	42
		area 1/2	15/15	13/13	21/21
nominal cross section/ effective* per area		area 1	2350/1175	1900/950	3250/1625
		area 1/2	1150/575	925/463	1600/800

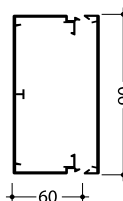





LFF600900					
number of cables	power current 3 x 2.5 mm ²	area 1	21	19	29
		area 1/2	10/10	9/9	14/14
	vlv data current L 120 - 4 pairs	area 1	47	44	58
		area 1/2	23/23	21/21	29/29
nominal cross section/ effective* per area		area 1	3550/1775	3320/1660	4550/220
		area 1/2	1750/875	1635/817	2200/1100

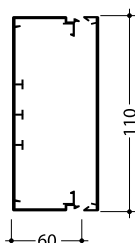

LFF6011000						
number of cables	power current 3 x 2.5 mm ²	area 1	25	24	12	35
		area 1/2	12/12	11/11	6/6	19/19
	vlv data current L 120 - 4 pairs	area 1	58	53	26	70
		area 1/2	28/28	25/25	12/12	35/35
nominal cross section/ effective* per area		area 1	4400/2200	4000/2000	1960/980	5500/2600
		area 1/2	2150/1075	1950/975	930/450	2600/1300

⁽¹⁾ area 1 = for trunking without partition
⁽²⁾ area 1/2 = for trunking with partition in the middle






LFF, FB

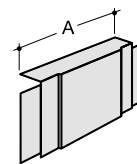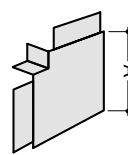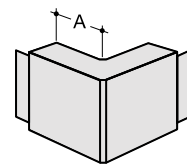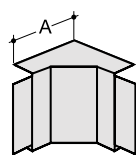





references	Internal corner size in mm	External corner size in mm	Flat corner size in mm	T piece size in mm
LFF200350 / 200360	35	35	43	92
LFF300300	60	30	60	130
LFF300450	60	30	60	130
LFF300600 *	75	55	85	170
LFF400400	85	45	65	170
LFF400900 *	115	70	128	170
LFF401100 *	115	70	148	190
LFF600600 *	130	69	91	170
LFF600900 *	138	50	128	170
LFF601100 *	138	50	148	190
LFF601500	130	69	180	250
LFF601900	130	69	220	290
LFF602300	130	69	260	290
FB601100	130	69	140	190
FB601300	130	69	160	210
FB601500	130	69	180	250
FB601900	130	69	220	290
FB602300	130	69	260	290
FB801300	240	160	176	-
FB992300	250	250	300	-

* Adjustable internal and external corners

   CLM

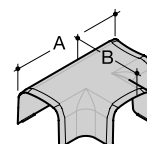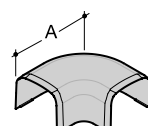

references	Internal corner size in mm	External cover size in mm	Flat corner size in mm	T piece size in mm	End caps size in mm
CLM30035	60	18	65	-	50
CLMU50065	95	30	110	A = 160 / B = 110	90
CLMU65090	110	30	135	A = 180 / B = 130	105
CLM75125	130	35	175	A = 230 / B = 183	125

  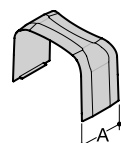 

references	Wall deviation size in mm	Lid cover joint size in mm	Wall joint size in mm	Reducer size in mm
CLM30035	A = 65 / B = 60	20	A = 44 / B = 60	-
CLMU50065	A = 110 / B = 100	25	A = 100 / B = 70	-
CLMU65090	A = 125 / B = 125	30	A = 125 / B = 85	-
CLM75125	A = 125 / B = 150	35	A = 125 / B = 100	70