

Hager Dream

Live your dream



1 gang switch
WGDL111 - 16AX 1 way
WGDL112 - 16AX 2 way
WGDL111N - 16AX 1 way w/ LED
WGDL112N - 16AX 2 way w/ LED



 
2 gang switch
WGDL121 - 16AX 1 way
WGDL122 - 16AX 2 way
WGDL121N - 16AX 1 way w/ LED
WGDL122N - 16AX 2 way w/ LED




3 gang switch
WGDL131 - 16AX 1 way
WGDL132 - 16AX 2 way
WGDL131N - 16AX 1 way w/ LED
WGDL132N - 16AX 2 way w/ LED



4 gang switch
WGDL141 - 16AX 1 way
WGDL142 - 16AX 2 way



 
1 gang press switch
WGDL111P - 10A
WGDL111NP - 10A w/ 220V LED
WGDL111NP-12V - 10A w/ 12V LED



2 gang press switch
WGDL121P - 10A
WGDL121NP - 10A w/ 220V LED
WGDL121NP-12V - 10A w/ 12V LED



 3 gang press switch
WGDL131P - 10A
WGDL131NP - 10A w/ 220V LED
WGDL131NP-12V - 10A w/ 12V LED



Intermediate
WGDL113 - 10AX 1 gang



Dimmer
WGDEDR500 - 40-500W single 2 way



Fan control
WGDEFR250 - 250VA single



Bell & EXIT switch
WGDL111B - mark "bell symbol"
WGDL111E - mark "EXIT"



20AX DP control switch
WGDL2D1 - 20AX 1 gang
WGDL2D2 - 20AX 2 gang
WGDL2D1N - 20AX 1 gang with LED
WGDL2D2N - 20AX 2 gang with LED
WGDL2D12N - 20AX 1 gang 2 way w/ LED



32A/ 45A DP control switch
WGDR32D1 - 32A 1 gang w/ LED
WGDR45D1 - 45A 1 gang w/ LED



Connection unit
WGDR25 - 25A w/ flex outlet



Fused connection unit
WGDR13N - 13A fused w/ LED
 + flex outlet



Fused connection unit
WGDR13SN - 13A switched fused
 w/ flex outlet, w/ LED




13A single socket outlet
WGDS113 - single
WGDS113S - single switched
WGDS113SN - single switched w/ LED
WGDS113N - single switched double pole



13A USB single socket outlet
WGDS113SUSB - single switched
 + 2 x USB charger
WGDS113S1USB - single switched
 + 1 x USB charger



13A socket outlet
WGDS213S - twin switched
WGDS213SN - twin switched w/ LED
WGDS213SDP - twin switched double pole

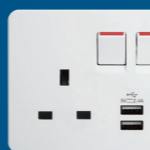

13A socket outlet
WGDS213SUSB - twin switched
 + 2 x USB charger



10A/15A socket outlet
WGDS110US - 10A, 2 pin switched universal
WGDS210U - 10A, 2 pin + 2 pin universal
WGDS115S - 15A round pin switched




16A socket outlet
WGDS116EA - single Euro-American
WGDS216EA - twin Euro-American



16A German socket
WGDS116S - single German
 w/ shutter



RJ11 telephone outlet
WGDT1RJ - 1 mod
WGDT2RJ - 2 mod

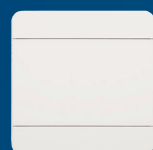

Sleeping light
WGDSL - Sleeping light (0.25W)



RJ45 cat6 outlet
WGDT1RJ6 - 1 mod
WGDT1RJ6NM - 1 mod w/o symbol
WGDT2RJ6 - 2 mod
WGDT2RJ6NM - 2 mod w/o symbol



RJ45 cat5e outlet
WGDT1RJ5 - 1 mod
WGDT2RJ5 - 2 mod




RJ11 + RJ45 outlet
WGDT2RJRJ5 - RJ11+RJ45 cat5e
 2 mod
WGDT2RJRJ6 - RJ11+RJ45 cat6
 2 mod



TV & Data inlet/outlet
WGDT2TVRJ5 - TV inlet/ outlet + RJ45 cat5e



TV inlet/outlet
WGDT1TV - TV inlet/ outlet, 1 mod
WGDT1TVF - TV outlet, F type, 1 mod

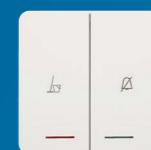

Hotel range
WGDHDC - 16AX, DND & MUR
 w/ LED (Indoor)
WGDHBD - 4A DND & MUR
 indicator w/ bell switch
WGDKTM - 16A key tag-mechanical
WGDKTRFID - 16A key tag- RFID



WA covers
XC9003 - IP55, single size
XC9004 - IP55, twin size



Hotel range
WGDS3USB - USB charger
 (1 x type C) + (2 x type A)
WGDEE1 - Emergency switch
WGDEA6 - 6W Audio switch



Accommodation plate
Dream/gallery*
WGDVE2 - Plate for Euro enhanced
 function*



Shaver socket
WGDHSR - 115/230V



Blank plate
WGDHP1 - size 1



Multi-gang frame
WGDC2 - 2 gang horizontal
WGDC3 - 3 gang horizontal
WGDC4 - 4 gang horizontal
WGDC5 - 5 gang horizontal



Color ranges
 Interstellar Grey



Noble Bronze



Knight Black



Elegant Gold

Remark: blue reference product - coming soon

*gallery: European wiring accessories functions

hager.com/intl-en

hager