

Hager Inspire

Design for a better life



1 gang switch
WGCL111 - 16AX 1 way
WGCL112 - 16AX 2 way
WGCL111P - 10A Press



2 gang switch
WGCL121 - 16AX 1 way
WGCL122 - 16AX 2 way
WGCL121P - 10A Press



3 gang switch
WGCL131 - 16AX 1 way
WGCL132 - 16AX 2 way
WGCL131P - 10A Press




4 gang switch
WGCL141 - 16AX 1 way
WGCL142 - 16AX 2 way
WGCL141P - 10A Press



1 gang switch w/ fluorescence
WGCL111F - 16AX 1 way
WGCL112F - 16AX 2 way



2 gang switch w/ fluorescence
WGCL121F - 16AX 1 way
WGCL122F - 16AX 2 way

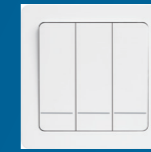

3 gang switch w/ fluorescence
WGCL131F - 16AX 1 way
WGCL132F - 16AX 2 way




4 gang switch w/ fluorescence
WGCL141F - 16AX 1 way
WGCL142F - 16AX 2 way



1 gang round switch
WGCR111 - 16AX 1 way
WGCR112 - 16AX 2 way
WGCR111P - 10A Press



2 gang round switch
WGCR121 - 16AX 1 way
WGCR122 - 16AX 2 way
WGCR121P - 10A Press

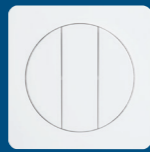

3 gang round switch
WGCR131 - 16AX 1 way
WGCR132 - 16AX 2 way
WGCR131P - 10A Press



Intermediate
WGCL113 - 10AX 1 gang



Bell & EXIT switch
WGCL111B - mark "bell symbol"
WGCL111E - mark "EXIT"



Dimmer
WGCEDR500 - 40-500W single 2 way



Fan control
WGCEFR250 - 250VA single



20AX DP control switch
WGCL2D1 - 20AX 1 gang
WGCL2D2 - 20AX 2 gang
WGCL2D1N - 20AX 1 gang with LED
WGCL2D2N - 20AX 2 gang with LED
WGCL2D12N - 20AX 1 gang 2 way w/ LED



32A/45A DP control switch
WGCR32D1 - 32A 1 gang w/ LED
WGCR45D1 - 45A 1 gang w/ LED




13A single socket outlet
WGCS113S - single switched
WGCS113SN - single switched w/ LED
WGCS113SDP - single switched double pole



13A USB single socket outlet
WGCS113SUSB - single switched
 + 2 x USB charger



13A socket outlet
WGCS213S - twin switched
WGCS213SN - twin switched w/ LED
WGCS213SDP - twin switched double pole

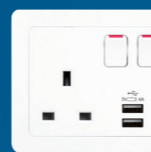

13A USB twin socket outlet
WGCS213SUSB - twin switched
 + 2 x USB charger



10A/15A socket outlet
WGCS210U - 10A, 2 pin
 + 2 pin universal
WGCS115S - 15A round
 pin switched



16A German socket
WGCS116S - single German
 w/ shutter



16A socket outlet
WGCS116EA - single Euro-American
WGCS216EA - twin Euro-American



RJ11 telephone outlet
WGCT1RJ - 1 mod
WGCT2RJ - 2 mod



RJ45 cat6 outlet
WGCT1RJ6 - 1 mod
WGCT1RJ6NM - 1 mod w/o symbol
WGCT2RJ6 - 2 mod
WGCT2RJ6NM - 2 mod w/o symbol



RJ45 cat5e outlet
WGCT1RJ5 - 1 mod
WGCT2RJ5 - 2 mod



RJ11 + RJ45 outlet
WGCT2RJRJ5 - RJ11+RJ45 cat5e
 2 mod
WGCT2RJRJ6 - RJ11+RJ45 cat6
 2 mod



TV & Data inlet/outlet
WGCT2TVRJ5 - TV inlet/ outlet
 + RJ45 cat5e



TV inlet/outlet
WGCT1TV - TV inlet/ outlet, 1 mod
WGCT1TVF - TV outlet, F type, 1 mod



Hotel range
WGCHDC - 16AX, DND & MUR w/ LED (Indoor)
WGCS3USB - USB charger
 (1 x type C) + (2 x type A)
WGCEE1 - Emergency switch
WGCEA6 - 6W Audio switch
WGCHKTM - 16A key tag- mechanical
WGCHKTRFID - 16A key tag- RFID



WA covers
XC9003 - IP55, single size
XC9004 - IP55, twin size



Shaver socket
WGCHSR - 115/230V



Accommodation plate Inspire/gallery*
WGCV2 - Plate for Euro enhanced
 function*



Multi-gang frame
Horizontal
WGCH2 - 2 gang
WGCH3 - 3 gang
WGCH4 - 4 gang
WGCH5 - 5 gang
Vertical
WGCV2 - 2 gang
WGCV3 - 3 gang



Blank plate
WGCBP1 - blank plate



Frame
WGCC2 - 2 gang
WGCC1S - 1 gang, square
WGCC1R - 1 gang, round



Color ranges
 Aurora Silver



Noble Bronze



Knight Black



Elegant Gold

Remark: blue reference product - coming soon
 *gallery: European wiring accessories functions

hager.com/intl-en

hager