

Hager Muse

Design for comfort and safety



1 gang switch
WGML111 - 16AX 1 way
WGML112 - 16AX 2 way
WGML111P - 10A Press
WGML113 - 10AX Intermediate




2 gang switch
WGML121 - 16AX 1 way
WGML122 - 16AX 2 way
WGML121P - 10A Press



3 gang switch
WGML131 - 16AX 1 way
WGML132 - 16AX 2 way
WGML131P - 10A Press



4 gang switch
WGML141 - 16AX 1 way
WGML142 - 16AX 2 way
WGML141P - 10A Press

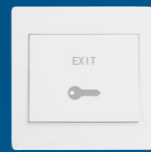

Bell & EXIT switch
WGML111B - mark "bell symbol"
WGML111E - mark "EXIT"



Fan control
WGMEFR250 - 250VA single



Dimmer
WGMEDR500 - 40-500W single 2 way



20AX DP control switch
WGML2D1 - 20AX 1 gang
WGML2D2 - 20AX 2 gang
WGML2D1N - 20AX 1 gang with LED
WGML2D2N - 20AX 2 gang with LED
WGML2D12N - 20AX 1 gang 2 way w/ LED



32A/ 45A DP control switch
WGMR32D1 - 32A 1 gang w/ LED
WGMR45D1 - 45A 1 gang w/ LED



45A DP Cooker unit
WGMR45CCU - size 2




Connection unit
WGMR25 - 25A w/ flex outlet
WGMR45 - 45A w/ flex outlet



Fused connection unit
WGMR13 - 13A fused w/ flex outlet
WGMR13N - 13A fused w/ LED + flex outlet




Fused connection unit
WGMR13S - 13A switched fused w/ flex outlet
WGMR13SN - 13A switched fused w/ flex outlet, w/ LED

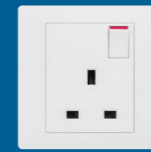

13A single socket outlet
WGMS113 - single
WGMS113S - single switched
WGMS113SN - single switched w/ LED
WGMS113SDP - single switched double pole




13A USB single socket outlet
WGMS113SUSB - single switched + 2 x USB charger
WGMS113S1USB - single switched + 1 x USB charger

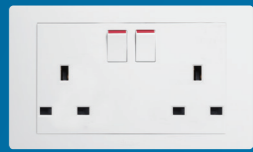

13A socket outlet
WGMS213 - twin
WGMS213S - twin switched
WGMS213SN - twin switched w/ LED
WGMS213SDP - twin switched double pole



13A socket outlet
WGMS213SUSB - twin switched + 2 x USB charger

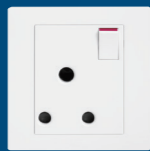

10A/15A socket outlet
WGMS110US - 10A, 2 pin switched universal
WGMS210U - 10A, 2 pin + 2 pin universal
WGMS115S - 15A round pin switched



16A socket outlet
WGMS116EA - single Euro-American
WGMS216EA - twin Euro-American



16A German socket
WGMS116S - single German w/ shutter



RJ11 telephone outlet
WGMT1RJ - 1 mod
WGMT2RJ - 2 mod



RJ45 cat6 outlet
WGMT1RJ6 - 1 mod
WGMT1RJ6NM - 1 mod w/o symbol
WGMT2RJ6 - 2 mod
WGMT2RJ6NM - 2 mod w/o symbol




RJ45 cat5 outlet
WGMT1RJ5 - 1 mod
WGMT2RJ5 - 2 mod



RJ11 + RJ45 outlet
WGMT2RJRJ5 - RJ11+RJ45 cat5e, 2 mod
WGMT2RJRJ6 - RJ11+RJ45 cat6, 2 mod



TV & Data inlet/outlet
WGMT2TVRJ5 - TV inlet/ outlet + RJ45 cat5e 2 mod

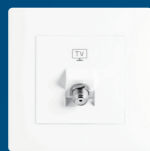

TV inlet/outlet
WGMT1TV - TV inlet/ outlet, 1 mod
WGMT1TVF - TV outlet, F type, 1 mod



USB charger
WGMS3USB - USB charger (1 x type C) + (2 x type A)



Hotel range
WGMHDC - 16AX, DND & MUR w/ LED (Indoor)
WGMEA6 - 6W Audio switch
WGMHKTM - 16A key tag- mechanical
WGMHKTRFID - 16A key tag- RFID



Multi-gang frame, horizontal
WGMCH2 - 2 gang
WGMCH3 - 3 gang
WGMCH4 - 4 gang
WGMCH5 - 5 gang



Frame
WGMCV1 - 1 gang (Vertical) 52 x 65mm
WGMC2 - 2 gang
WGMC1 - 1 gang (Horizontal) 65 x 52mm
WGMC1S - 1 gang (square) 52 x 52mm



Door chime
WXEDC01 - Electronic




WA covers
XC9003 - IP55, single size
XC9004 - IP55, twin size



Blank plate
WGMBP1 - size 1
WGMBP2 - size 2




Accommodation plate Muse/gallery*
WGMVE2 - Plate for Euro enhanced function

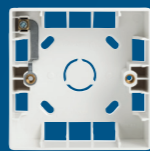

Surface mounting box
WGMB351 - single, 35mm depth
WGMB352 - twin, 35mm depth



Color ranges
 Aurora Sliver

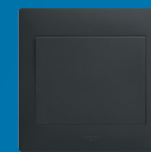

Knight Black

Remark: blue reference product - coming soon
 *gallery: European wiring accessories functions

hager.com/intl-en

hager